



Digital metering instruments DMK series

DMK... to view 3 to 39 electrical parameters


- Voltmeters
- Ammeters
- Frequency meter and cos-phi meter
- Combined voltage, current and watt meter
- Versions: single or three-phase, with or without relay output.

DMK... to view 47 electrical parameters

- Basic version
- Basic version plus energy meters
- Basic version plus energy meters plus RS485 port
- Versions for generating set duty.

DMK... to view 251 electrical parameters

- Basic version
- Basic version plus 2 programmable outputs
- Basic version plus 2 programmable outputs plus RS485 port
- Basic version plus data-loggers plus RS285 and RS485 ports.

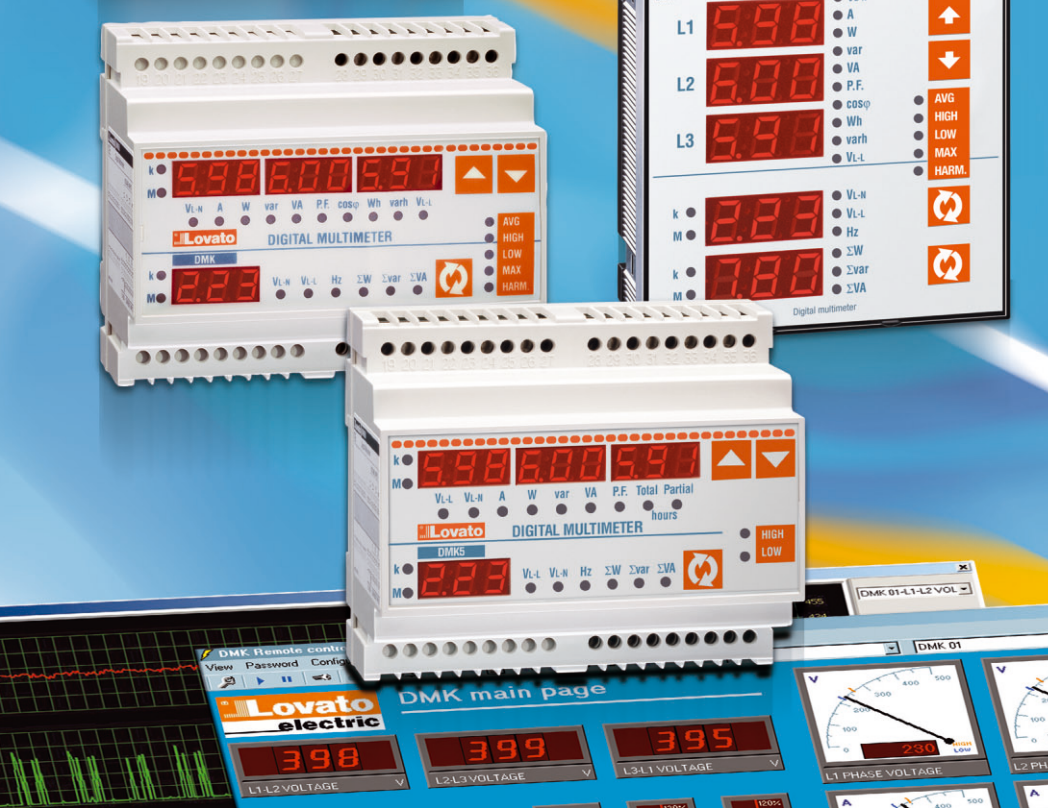

100% electricity

LOVATO ELECTRIC S.P.A.
CONTROL SOLUTIONS
FOR INDUSTRY

VIA DON E. MAZZA, 12
24020 GORLE (BG) ITALY

Tel.: +39 035 4282111
Fax: +39 035 4282400
E-mail: info@LovatoElectric.com

www.LovatoElectric.com