


Lovato
electric

LOVATO ELECTRIC S.P.A.

24020 GORLE (BERGAMO) ITALIA
VIA DON E. MAZZA, 12
TEL. 035 4282111
TELEFAX (Nazionale): 035 4282200
TELEFAX (International): +39 035 4282400
E-mail info@LovatoElectric.com
Web www.LovatoElectric.com



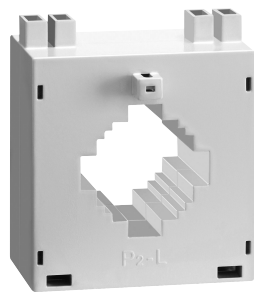


- ① TRASFORMATORI DI CORRENTE - TIPO A FORO PASSANTE
- ② CURRENT TRANSFORMERS - SOLID CORE TYPE
- ③ STROMWANDLER - AUFSTECK-TYP
- ④ TRANSFORMATEURS D'INTENSITE - TYPE A PASSAGE
- ⑤ TRANSFORMADORES DE CORRIENTE - TIPO PASANTE






DM...T




DM1T... - DM2T... - DM3T...

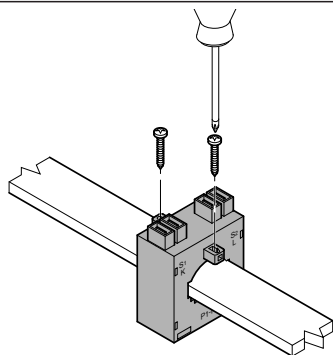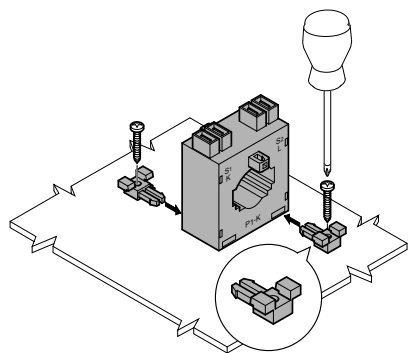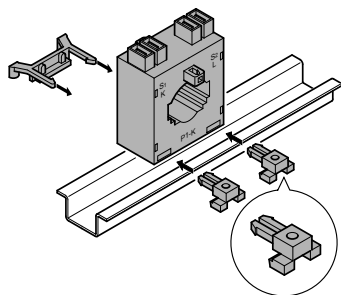


DM4T...

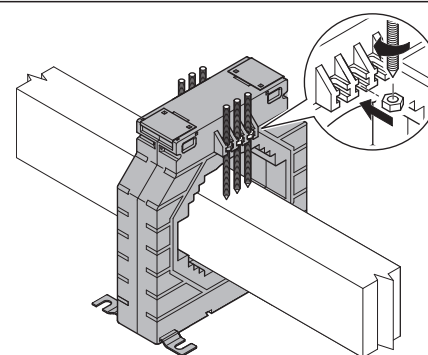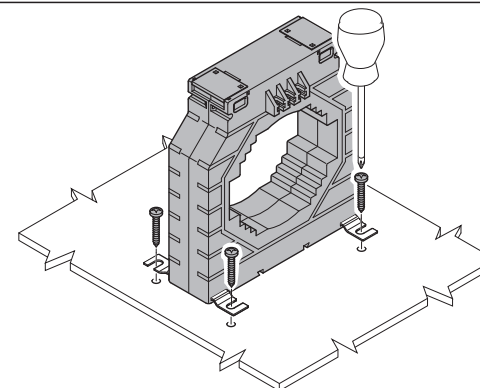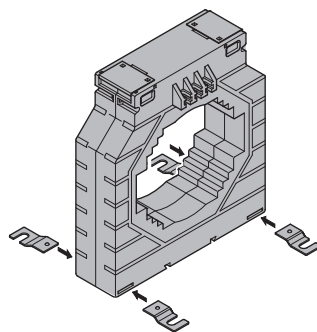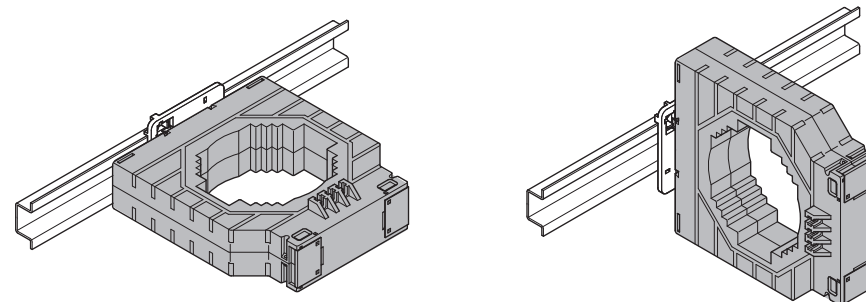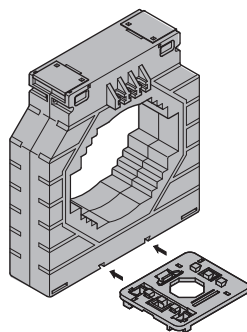



DM1T... - DM2T... - DM3T...

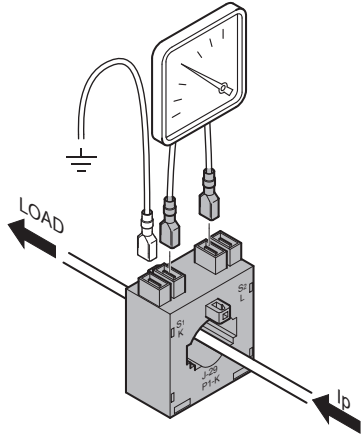


DM...T

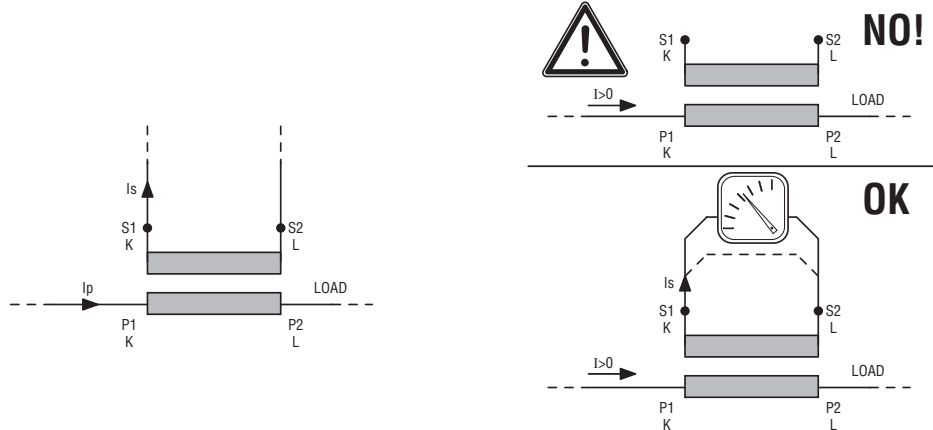


DM4T...

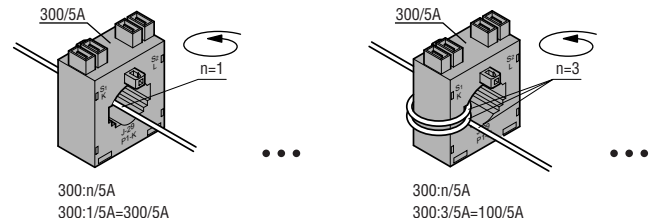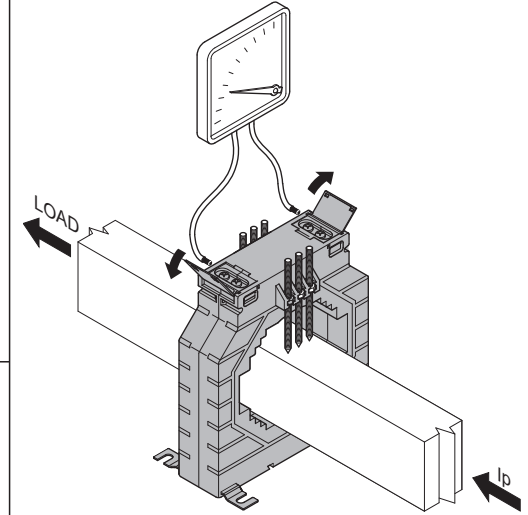


DM1T...

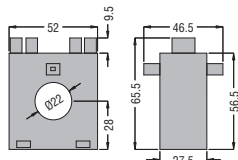


DM2T...

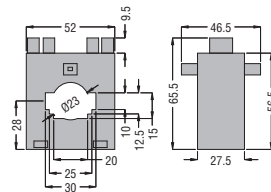

DM3T...

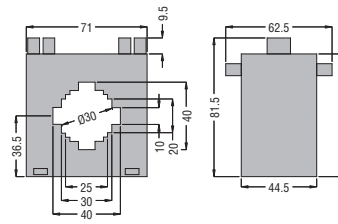

DM4T...

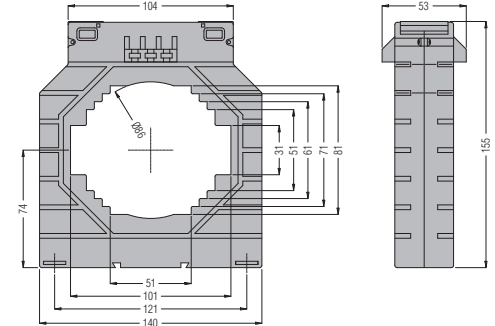

= Ø22mm

= Ø23mm
 = 30x10mm
 = 25x12.5mm
 = 20x15mm

= Ø30mm
 = 40x10mm
 = 30x20mm
 = 25x25mm

= Ø86mm
 = 100x30mm
 = 80x50mm
 = 70x60mm

	I _p /5 [A]	cl./kl. 0.5 [VA]	cl./kl. 1 [VA]
DM1T 0040	40	—	1
DM1T 0050	50	—	1.5
DM1T 0060	60	—	2
DM1T 0080	80	—	2.5
DM1T 0100	100	—	2.5
DM1T 0150	150	—	2.5

	I _p /5 [A]	cl./kl. 0.5 [VA]	cl./kl. 1 [VA]
DM2T 0060	60	—	1
DM2T 0080	80	—	1
DM2T 0100	100	—	1.5
DM2T 0150	150	—	1.5
DM2T 0200	200	—	2.5
DM2T 0250	250	—	2.5
DM2T 0300	300	1.5	3
DM2T 0400	400	2	3

	I _p /5 [A]	cl./kl. 0.5 [VA]	cl./kl. 1 [VA]
DM3T 0200	200	—	5
DM3T 0250	250	—	5
DM3T 0300	300	2.5	5
DM3T 0400	400	2.5	5
DM3T 0500	500	2.5	5
DM3T 0600	600	5	10
DM3T 0800	800	5	10
DM3T 1000	1000	5	10

	I _p /5 [A]	cl./kl. 0.5 [VA]	cl./kl. 1 [VA]
DM4T 1200	1200	15	30
DM4T 1250	1250	15	30
DM4T 1500	1500	30	30
DM4T 1600	1600	30	30
DM4T 2000	2000	45	45
DM4T 2500	2500	45	45
DM4T 3000	3000	45	45
DM4T 3500	3500	50	50
DM4T 4000	4000	50	50